



Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Coax	1
Number of contacts Low Voltage	5
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Size	3S
Matching parts	FFP.3S.805.CTAC63Z
Series	S - Indoor Stepped Insert

Technical details

Electrical Configuration

Contact Termination Low voltage	Solder
Nb of contacts Coax	1
Contact Termination Coax	Solder
Insert configuration value	3S.805 - 1 Coax (50 Ohm), 5 Low V.
Insulator	T: PTFE
Rated current	8 Amps
Impedance	50 Ohm
Vtest	2100 V (AC), 3000 V (DC)
Vtest (contact-shell)	1800 V (AC), 2550 V (DC)
Number of contacts Low Voltage	5

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/psp-3s-805-ctlc63z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Form & Material

Shell style / Model id	PSP - Fixed receptacle, nut fixing, cable collet and inner anti-rotating device
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with female pin 1
Variant	Nut for fitting a bend relief
Weight	58.87 g


Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet

Drawings

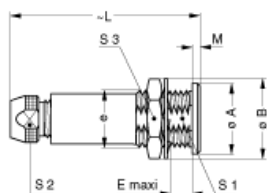

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/psp-3s-805-ctlc63z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Dimensions

	A	B	e	E	L	M	S1	S2	S3
mm.	22	25.2	M18x1.0	11.5	59	2	16.5	14	22
in.	0.87	0.99		0.45	2.32	0.08	0.65	0.55	0.87

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/psp-3s-805-ctlc63z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.