



## Summary

[Request a quote](#)

[Catalog](#)

Fiber optic	2
Number of contacts Low Voltage	2
Number of contacts High Voltage	2
Wire Size/AWG	24 - 20
Socket / Receptacle	Socket / Receptacle - Free
Locking system	Push-pull
Jacket cable outside diameter [mm]	8.90 - 9.50 mm
Size	3K
Matching parts	<a href="#">FUW.3K.93C.YSEC96</a>
Series	3K.93C.Y - SMPTE Hybrid

## Technical details

[https://www.lemo.com/int\\_en/solutions/specialties/3k-93c-y-smpte-hybrid/puw-3k-93c-ysec96.html](https://www.lemo.com/int_en/solutions/specialties/3k-93c-y-smpte-hybrid/puw-3k-93c-ysec96.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Electrical Configuration

Contact Termination Low voltage	Crimp
Fiber optic	2
Insert configuration value	3K.93C - 2 FO Type F2, 2 HV + 2 LV
Rated current	10 Amps
Fiber Optic Contact	Type F2
Vtest power/signal (AC)	2250V , 1000V
Working voltage power/signal(AC)	600V , 42V
Cable type	Cable type: A  SMPTE 311M or EBU R100 S
Number of contacts Low Voltage	2
Number of contacts High Voltage	2
Wire Size/AWG	24 - 20

## Form & Material

Shell style / Model id	PU - Free receptacle, 'Y' design, cable collet adapter and long shell for fitting a bend relief with cap (with enhanced screen efficiency)
Socket / Receptacle	Free
Housing material	Special housing (see notes for details)
Locking system	Push-pull
Keying	5 keys (alpha=95, beta=115, gamma=20, delta=30, plug: female LV, male HV, female FO contacts)
Weight	110.58 g

## Environment

Environmental protection (IP rating)	IP68
Minimal temperature	-40°C / +80°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]


 
[https://www.lemo.com/int\\_en/solutions/specialties/3k-93c-y-smpte-hybrid/puw-3k-93c-ysec96.html](https://www.lemo.com/int_en/solutions/specialties/3k-93c-y-smpte-hybrid/puw-3k-93c-ysec96.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	8.90 - 9.50 mm

## Drawings

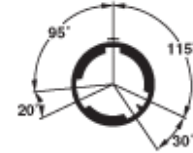

## Dimensions

	A	L
mm.	23	98
in.	0.91	3.86

[https://www.lemo.com/int\\_en/solutions/specialties/3k-93c-y-smpte-hybrid/puw-3k-93c-ysec96.html](https://www.lemo.com/int_en/solutions/specialties/3k-93c-y-smpte-hybrid/puw-3k-93c-ysec96.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.