



Summary

[Request a quote](#)

[Catalog](#)

| | |
|---------------------|-----------------------------------|
| Triax | 1 |
| Socket / Receptacle | Socket / Receptacle - Free |
| Locking system | Push-pull |
| Size | 4A |
| Matching parts | FFB.4A.675.CTCC85 |

Technical details

Electrical Configuration

| | |
|----------------------------|---------------------------|
| Triax | 1 |
| Insert configuration value | 4A.675 - 1 Triax (75 Ohm) |
| Insulator | T: PTFE |
| Rated current | 6 Amps |

Form & Material

| | |
|------------------------|---|
| Shell style / Model id | PXA - Free receptacle with cable collet and earthing crown |
| Socket / Receptacle | Free |
| Housing material | Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces |
| Locking system | Push-pull |
| Keying | 3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts) |
| Weight | 278.97 g |

https://www.lemo.com/int_en/pxa-4a-675-ctrc85.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Environment

| | |
|-----------------------------------|----------------------------|
| Environmental sealing (IP rating) | IP61 |
| Endurance | 5000 mating cycles |
| Climatical Category | 55/175/21 |
| Humidity (max) | <=95% [at 60 deg C /140 F] |
| Salt Spray Corrosion | >1000 hr |

Cable fixation

| | |
|------------------------------|--|
| Cable termination protection | Standard back nut (no additional protection) |
| Fixation type | Cable collet |

Drawings

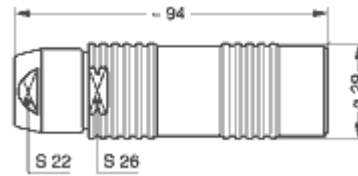

Dimensions

| | A | L | S1 | S2 |
|-----|----------|----------|-----------|-----------|
| mm. | 29 | 94 | 26 | 22 |
| in. | 1.14 | 3.7 | 1.02 | 0.87 |

https://www.lemo.com/int_en/pxa-4a-675-ctrc85.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.