



Summary

[Request a quote](#)

[Catalog](#)

Triax	1
Socket / Receptacle	Socket / Receptacle - Free
Locking system	Push-pull
Size	4A
Matching parts	FFB.4A.675.CTCC95

Technical details

Electrical Configuration

Triax	1
Insert configuration value	4A.675 - 1 Triax (75 Ohm)
Insulator	T: PTFE
Rated current	6 Amps

Form & Material

Shell style / Model id	PXA - Free receptacle with cable collet and earthing crown
Socket / Receptacle	Free
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Locking system	Push-pull
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)

https://www.lemo.com/int_en/pxa-4a-675-ntrc95.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Environment

Environmental protection (IP rating)	IP61
Climatical Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Salt Spray Corrosion	>144 hr

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet

Drawings

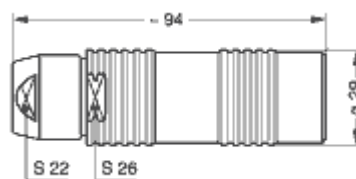

Dimensions

	A	L	S1	S2
mm.	29	94	26	22
in.	1.14	3.7	1.02	0.87

https://www.lemo.com/int_en/pxa-4a-675-ntrc95.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.