



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Locking system	Push-pull
Size	1

Technical details

Form & Material

Shell style / Model id	RGG.01 - Straight fixed coupler
Housing material	Aluminum alloy (anodized) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Weight	4.04 g


Environment

Environmental sealing (IP rating)	IP50
-----------------------------------	------

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
------------------------------	--

Drawings

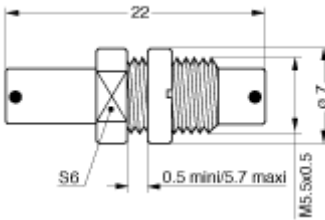

Dimensions

	A	e1	E _{max}	E _{min}	L	S2
mm.	7	M5x0.5	5.7	0.5	22	6
in.	0.28		0.22	0.02	0.87	0.24

https://www.lemo.com/int_en/rgg-01-f99-lne.html

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.