



Image for illustrative purpose only

## Summary

<a href="#">Request a quote</a>	
<a href="#">Catalog</a>	
Number of contacts Low Voltage	1
Locking system	Push-pull
Size	00
Suggested matching part	<a href="#">FFA.00.113.CTAC22</a>

# Technical details

## Electrical Configuration

Number of contacts Low Voltage	1
Insert configuration value	0.113 - 1 Low Voltage
Insulator	T: PTFE
Rated current	8 A
Vtest	850 V (AC), 1200 V (DC)
Contact Dia.	1.3


## Form & Material

Shell style / Model id	RMA - Free coupler
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, female
Colour	Grey
Weight	2.72 g

## Environment

Environmental sealing (IP rating)	IP50
Salt Spray Corrosion	>1000 hr

# Drawings

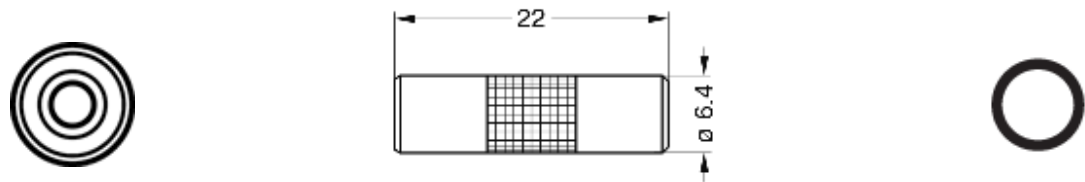

## Dimensions

	A	L
mm.	6.5	22
in.	0.26	0.87

[https://www.lemo.com/int\\_en/rma-00-113-ctm.html](https://www.lemo.com/int_en/rma-00-113-ctm.html)

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.