



Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	8
Wire Size/AWG	30 - 22
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	5.30 - 6.50 mm
Size	SP
Matching parts	SRN.M08.GLL.6G
Series	REDEL SP - Inner Push-Pull

Technical details

https://www.lemo.com/int_en/solutions/redel/redel-sp-inner-push-pull/san-m08-gla-6g.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Electrical Configuration

Contact Termination Low voltage	Solder
R (max)	8.5 mOhm
Insert configuration value	SP.M08 - 8 Low V.
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	5 Amps
Test voltage (kV rms) Contact-contact	1.50
Contact Type	Solder
Max. Solid Conductor	0.36 mm ² (AWG 23)
Max. Stranded Conductor	0.36 mm ² (AWG 22)
Air clearance	0.78 mm
Creepage distance	0.78 mm
Bucket Dia.	0.8 mm (0.032in)
Contact Dia.	0.9 mm (0.0354in)
Number of contacts Low Voltage	8
Wire Size/AWG	30 - 22

Form & Material

Shell style / Model id	SA - Straight plug, key (N) or keys (P, S and T), with grey cable collet
Plug	Straight
Housing material	Proprietary sulfone, gray
Locking system	Push-pull
Keying	3 keys (alpha=0, gamma=30, plug: male contacts, receptacle: female contacts)
Variant	Gray collet nut
Weight	47.31 g

Environment

Technical domain	Medical
Environmental protection (IP rating)	IP50
Minimal temperature	-50°C / +170°C

https://www.lemo.com/int_en/solutions/redel/redel-sp-inner-push-pull/san-m08-gla-6g.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	5.30 - 6.50 mm







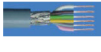
Recommended By Lemo

Accessories

Tools

Crimp tool	DPC.91.701.V
------------	------------------------------

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.08.T22.059QGC	TPR	Grey	
CMN.08.T22.059QGZE	TPR (medical)	Grey	
16080	PVC	Grey	
180240	PVC	Black	
180260	PVC	Black	
280250	PVC	Grey	
335990	PVC	Black	
335991	PVC	Black	
42265	PVC	Yellow	
80140	PVC	Grey	

https://www.lemo.com/int_en/solutions/redel/redel-sp-inner-push-pull/san-m08-gla-6g.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.