

## Summary

[Request a quote](#)

---

[Catalog](#)

---

Number of contacts Low Voltage	14
Gender	Standard
Locking system	Push-pull
Size	5K
Series	K - Outdoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/slg-5k-314-tlapve.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/slg-5k-314-tlapve.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Insert configuration value	5K.314 - 14 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	18 A
Vtest (contact-contact)	2100 V (AC), 2970 V (DC)
Vtest (contact-shell)	2000 V (AC), 2850 V (DC)
Contact Type	Solder
Contact Dia.	2 mm (0.08in)
Number of contacts Low Voltage	14
Gender	Standard

## Form & Material

Shell style / Model id	SLG - Fixed coupler, nut fixing, key (G) or keys (L) at the flange end, and key (G) or keys (C or L) at the other end, watertight or vacuumtight
Housing material	Stainless steel shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	Front side: 2 key (gamma=75, male) , Other side: 1 key (alpha=0, female)
Variant	PVE : Potted, vaccum-tested, EPDM
Weight	583.84 g



## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-20°C / +80°C
Climatical Category	20/80/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Pressure	5 bars
R leak (He) (max)	0.0000001 mbar*/s (if vacuum-tested)

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/slg-5k-314-tlapve.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/slg-5k-314-tlapve.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Drawings

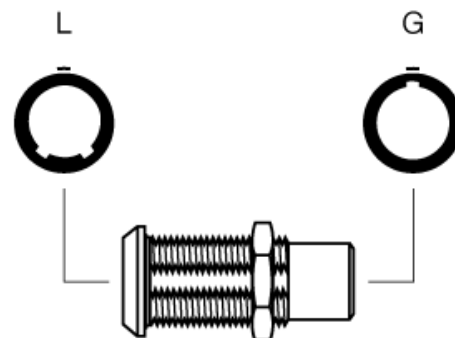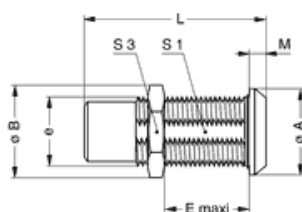

## Dimensions

	<b>A</b>	<b>B</b>	<b>e</b>	<b>E</b>	<b>L</b>	<b>M</b>	<b>S1</b>
mm.	55	54	M45x1.5	58	88	9	42.5
in.	2.17	2.13		2.28	3.46	0.35	1.67

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/slg-5k-314-tlapve.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/slg-5k-314-tlapve.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.