



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

| | |
|------------------------------------|---|
| Number of contacts Low Voltage | 4 |
| Wire Size/AWG | 28 - 20 |
| Gender | Standard |
| Socket / Receptacle | Socket / Receptacle - Fixed Panel Front Mounted |
| Locking system | Push-pull |
| Jacket cable outside diameter [mm] | 1.00 - 12.60 mm |
| Size | SP |
| Suggested matching part | SAN.M04.GLA.6G |
| Series | REDEL SP - Inner Push-Pull |

https://www.lemo.com/int_en/solutions/redel/redel-sp-inner-push-pull/sln-m04-gllg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

| | |
|---------------------------------|-------------------------------|
| Number of contacts Low Voltage | 4 |
| Contact Termination Low voltage | Solder |
| R (max) | 2.8 mOhm |
| Insert configuration value | SP.M04 - 4 Low V. |
| Insulator | L: PEEK (UL 94 / V-0/1.5) |
| Rated current | 11.5 A |
| Test voltage contact-contact | 2.26 (kV DC) |
| Max. Solid Conductor | 0.50 mm ² (AWG 20) |
| Max. Stranded Conductor | 0.50 mm ² (AWG 20) |
| Air clearance | 0.95 mm |
| Creepage distance | 0.95 mm |
| Bucket Dia. | 1.1 mm (0.04in) |
| Contact Dia. | 1.3 mm (0.0512in) |
| Wire Size/AWG | 28 - 20 |
| Gender | Standard |

Form & Material

| | |
|------------------------|--|
| Shell style / Model id | SL_SP - Fixed socket, key (N) or keys (P, S and T), nut fixing, grey front nut |
| Socket / Receptacle | Fixed Panel Front Mounted |
| Housing material | Proprietary sulfone, grey |
| Locking system | Push-pull |
| Keying | 3 keys (alpha=0, gamma=30, plug: male contacts, receptacle: female contacts) |
| Colour | Grey |
| Variant | Grey front nut |
| Weight | 4.36 g |

https://www.lemo.com/int_en/solutions/redel/redel-sp-inner-push-pull/sln-m04-gllg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



Environment

| | |
|-----------------------------------|---------------------|
| Technical domain | Medical |
| Environmental sealing (IP rating) | IP50 |
| Endurance | >5000 mating cycles |
| Temperature range | -50°C / +170°C |
| Steam sterilization | > 100 times |

Cable fixation

| | |
|------------------------------------|--|
| Cable termination protection | Standard back nut (no additional protection) |
| Jacket cable outside diameter [mm] | 1.00 - 12.60 mm |

Drawings

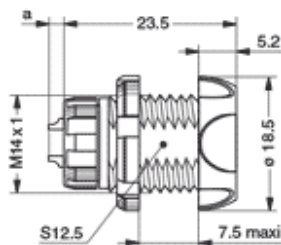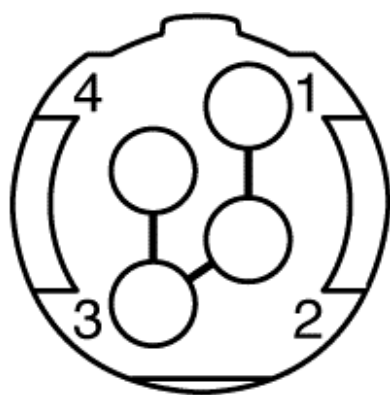

Dimensions

| | a | B | N | e |
|-----|----------|----------|----------|----------|
| mm. | 2.2 | 18.5 | 23.5 | M14x1 |
| in. | 0.09 | 0.73 | 0.93 | |

https://www.lemo.com/int_en/solutions/redel/redel-sp-inner-push-pull/sln-m04-gllg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cables

| Cable PartNumber | Material | Colour | Cable image |
|--------------------|---------------|--------|--|
| CMN.04.T20.053PGZE | | grey |  |
| CMN.04.T20.053PNZE | | |  |
| CMN.04.T20.053QGZE | TPR (medical) | Grey |  |
| CMN.04.T22.047QGC | TPR | Grey | |
| CMN.04.T22.048QGZE | TPR (medical) | Grey |  |
| CMN.04.T28.031PGCE | PVC | GREY |  |
| CMN.04.T28.031PGZE | | grey |  |
| CMN.04.T28.031PNCE | PVC | Black |  |
| CMN.04.T28.031PNZE | | |  |
| CMN.04.T28.031QGC | TPR | Grey | |
| 140240 | PVC | Black |  |
| 140250 | PVC | Grey |  |
| 240500 | PVC | Grey |  |
| 240750 | PVC | Grey |  |
| 40080 | PVC | Black | |
| 40086 | PVC | Blue | |
| 40140 | PVC | Black |  |
| 40240 | PTFE | White |  |
| 40260 | PVC | Black |  |
| 4041 | PVC | Grey |  |
| 4050 | PVC | Black |  |
| 4080 | PVC | Grey | |
| 417920 | PVC | Grey |  |
| 4220 | PVC | Black |  |
| 4221 | PVC | Black |  |
| 4260 | PTFE | White |  |
| 4280 | PVC | Black |  |
| 80080 | PVC | Grey | |
| 80082 | PVC | Red | |
| 80084 | PVC | Black | |
| CTR.75.030.121870G | PVC | Grey |  |

https://www.lemo.com/int_en/solutions/redel/redel-sp-inner-push-pull/sln-m04-gllg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.