



## Summary

[Request a quote](#)

---

[Catalog](#)

---

Number of contacts Low Voltage	10
Locking system	Push-pull
Size	3E
Series	E - Outdoor Stepped Insert

[https://www.lemo.com/int\\_en/solutions/originals/e-outdoor-stepped-insert/swh-3e-310-cllsv.html](https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/swh-3e-310-cllsv.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Insert configuration value	3E.310 - 10 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	9 A
Vtest	1060 V (AC), 1500 V (DC)
Contact Type	Solder
Contact Dia.	1.3
Number of contacts Low Voltage	10

## Form & Material

Shell style / Model id	SWH - Fixed coupler, nut fixing, watertight or vaccumtight, special potting
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying, pin 1 female on flange side, male on other side
Variant	Watertight / Vacuum-tested unmated (connector to device), special potting



## Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	Hermetic unmated
Endurance	5000 mating cycles
Climatical Category	20/80/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
R leak (He) (max)	0.0000001 mbar*l/s (if vacuum-tested)
Salt Spray Corrosion	>1000 hr

[https://www.lemo.com/int\\_en/solutions/originals/e-outdoor-stepped-insert/swh-3e-310-cllsv.html](https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/swh-3e-310-cllsv.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Drawings

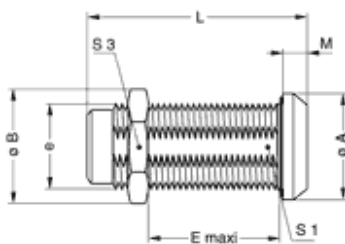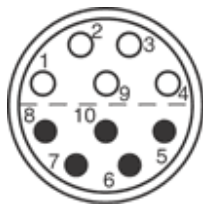

## Dimensions

	<b>A</b>	<b>B</b>	<b>e</b>	<b>E</b>	<b>L</b>	<b>M</b>	<b>S1</b>	<b>S3</b>
mm.	31	34.5	M24x1.0	33	64.2	6	22.5	30
in.	1.22	1.36		1.3	2.53	0.24	0.89	1.18

[https://www.lemo.com/int\\_en/solutions/originals/e-outdoor-stepped-insert/swh-3e-310-clsv.html](https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/swh-3e-310-clsv.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.