

LEMO 3K.93C PIGTAILS SPLICE BOX



LEMO 3K.93C Pigtailed Splice Box

Splicing and termination, Power connectors

The LEMO 3K.93C Pigtailed Splice Box is ideal wall mount interconnect indoor cabinet designed for splice, storage and protection up to 4 LEMO 3K.93C Pigtail connectors and with 4 power Plastic connectors MATE-N-LOK (6 way).

These compact, modular units are ideal for use in Broadcast Infrastructure Network inside the Camera Boxes or Patch Panels. It is designed with compact size which can fit for cabinets with minimum depth of 15 cm. It allows to use different types of optical adapters (SC/Duplex LC).

This is the ideal method to fix 3K.93C connectors at any site for Broadcast Infrastructure Systems.

Key Features:

- Modular system
- Small dimensions and low weight
- Craft friendly - protection for facility and user connections
- Easy wall mounting
- Easy exchangeable panel for most common optical connector types (SC/Duplex LC)
- Cable clamps inside for firm holding of hybrid cable




Technical specifications

Part Number	Description LEMO 3K.93C Splice Box	Dimensions (mm)	Ship weight (kg)
WST.SB.4M.C	4 way; SC fibre connectors	180 x 140 x 65	0.45
WST.SB.4M.2L	4 way; Duplex LC fibre connectors	180 x 140 x 65	0.45
WST.SB.2M.C	2 way; SC fibre connectors	180 x 140 x 65	0.45
WST.SB.2M.2L	2 way; Duplex LC fibre connectors	180 x 140 x 65	0.45

Used for Splicing and Termination of LEMO 3K.93C Pigtails


MXT.3K.93C.ZZZC100 - Pre Terminated FXW Pigtail (ECU side pigtails)

Assembly cable with one fixed plug (FXW) and one pigtail (LC) complete with BHA cap.

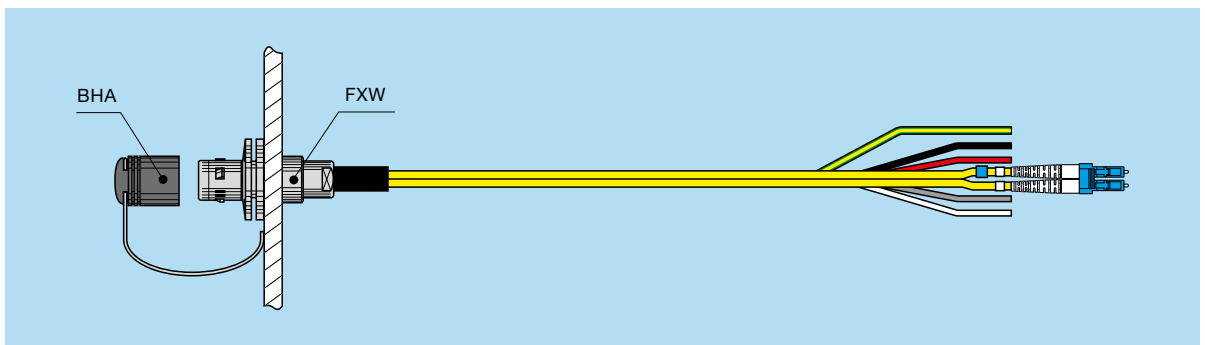

MDT.3K.93C.ZZZC100 - Pre Terminated EDW Pigtail (Camera side pigtails)

Assembly cable with one fixed socket (EDW) and one pigtail (LC) complete with BRA cap.

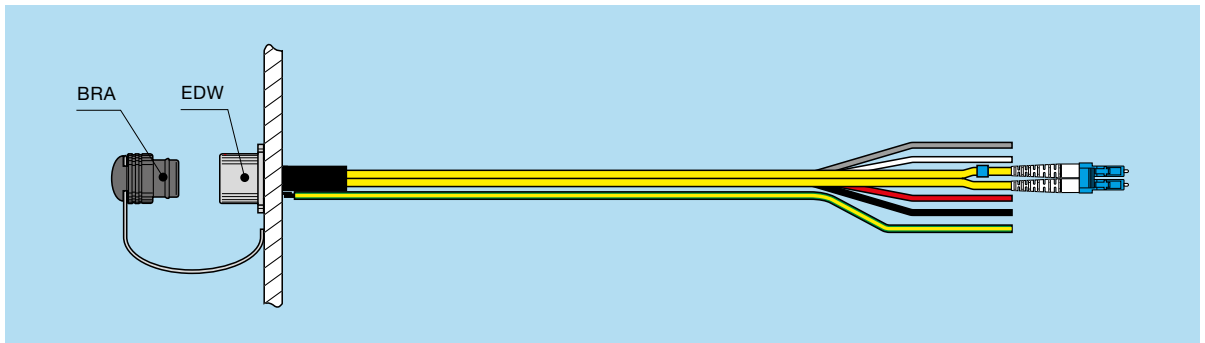

LEMO HEADQUARTERS

LEMO SA (SWITZERLAND)
Chemin des Champs-Courbes 28
P.O. Box 194 - CH-1024 Ecublens
Tel. (+41 21) 695 16 00 - info@lemo.com

LEMO MIDDLE EAST
6th Floor, Concord Tower, Dubai Media City
P.O. Box: 126732 Dubai, UAE
Tel. (+971) 4 454 9833 - info-me@lemo.com

www.lemo.com

Product safety notice & disclaimers:

Please read and follow all instructions specified on <https://www.lemo.com/en/about-lemo/product-safety-notice-and-disclaimers>