



## Summary

[Request a quote](#)

[Catalog](#)

Locking system	Threaded
Size	0V

## Technical details

### Form & Material

Shell style / Model id	BRE - Cap for receptacle
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Locking system	Threaded
Keying	Circular, female
Weight	12.58 g


### Environment

Environmental protection (IP rating)	IP68
Minimal temperature	-20°C / +135°C
Climatical Category	20/200/21
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Pressure	30 bars
Salt Spray Corrosion	>144 hr

[https://www.lemo.com/int\\_en/bre-0v-200-nav.html](https://www.lemo.com/int_en/bre-0v-200-nav.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Drawings

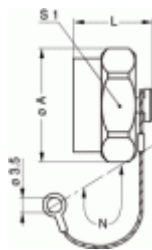

## Dimensions

	<b>A</b>	<b>L</b>	<b>N</b>	<b>S1</b>
mm.	17.2	13.7	85	16
in.	0.68	0.54	3.35	0.63

[https://www.lemo.com/int\\_en/bre-0v-200-nav.html](https://www.lemo.com/int_en/bre-0v-200-nav.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.