



Summary

[Request a quote](#)

[Catalog](#)

Coax	4
Number of contacts Low Voltage	9
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	4.00 - 28.60 mm
Size	4K
Series	K - Outdoor keyed

Technical details

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/eeg-4k-879-kll1.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Electrical Configuration

Contact Termination Low voltage	Solder
Coax	4
Contact Termination Coax	Crimp
R (max)	5.8 mOhm
Insert configuration value	4K.879 - 4 Coax (50 Ohm), 9 Low V.
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	7 Amps
Test voltage (kV rms)	0.9
Contact Type	Coaxial 50 Ohm (Crimp) Type C
Cable type	Cable type: A RG 174 A/U, RG 188 A/U, RG 316 /U S
Contact Dia.	0.7 mm (0.03in)
Number of contacts Low Voltage	9
Gender	Standard

Form & Material

Shell style / Model id	EE - Fixed receptacle, nut fixing (back panel mounting)
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	Brass (black chrome) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Weight	93.57 g

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental protection (IP rating)	IP68
Minimal temperature	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/eeg-4k-879-kii1.html



LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Jacket cable outside diameter [mm]

4.00 - 28.60 mm

Drawings

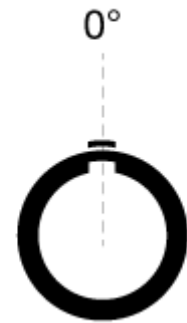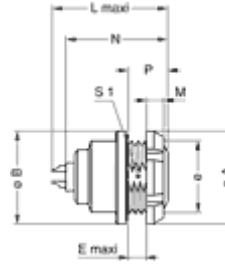

Dimensions

	N	M	L	E	e	B	A	S1	P
mm.	38.6	7	40.2	6	M30x1.0	37	41.5	28.5	13.5
in.	1.52	0.28	1.58	0.24		1.46	1.63	1.12	0.53

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/eeg-4k-879-kll1.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.