



## Summary

[Request a quote](#)

Number of contacts High Voltage	6
Wire Size/AWG	30 - 22
Gender	Reverse Gender
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.00 - 13.60 mm
Size	2B
Matching parts	<a href="#">FGJ.2B.436.CJAD72Z</a>
Series	B - Indoor keyed

## Technical details

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/eej-2b-436-cjl.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/eej-2b-436-cjl.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Electrical Configuration

Contact Termination High voltage	Solder
Insert configuration value	2B.436 - 6 High Voltage
Insulator	J: PEEK/PEEK
Rated current	3 Amps
Test voltage (kV AC)	6.4
Contact Type	Solder
Creepage distance	4.7 mm
Number of contacts High Voltage	6
Wire Size/AWG	30 - 22
Gender	Reverse Gender

## Form & Material

Shell style / Model id	EE - Fixed receptacle, nut fixing (back panel mounting)
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	2 keys (alpha=37.5, plug: female contacts, receptacle: male contacts)
Weight	14.88 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental protection (IP rating)	IP50
Minimal temperature	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr


[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/eej-2b-436-cjl.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/eej-2b-436-cjl.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Jacket cable outside diameter [mm]	2.00 - 13.60 mm
------------------------------------	-----------------

Drawings

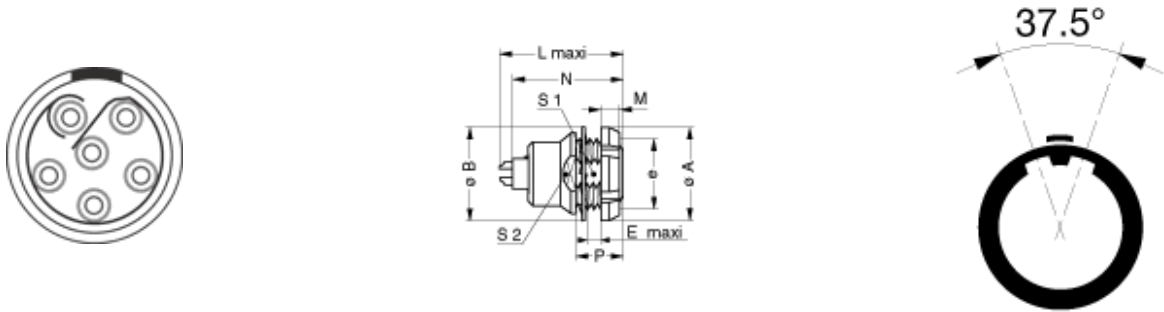

Dimensions

	B	e	E	L	M	N	P	S1	S2	A
mm.	20	M15x1.0	4.3	26.7	3.5	24.6	9	13.5	15	20
in.	0.79		0.17	1.05	0.14	0.97	0.35	0.53	0.59	0.79