



## Summary

[Request a quote](#)

[Catalog](#)

Low Voltage	5
Wire Size/AWG	36 - 28
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Matching parts	<a href="#">FGG.00.305.KLAD22Z</a>
Series	B - Indoor keyed

## Technical details

### Electrical Configuration

Contact Termination Low voltage	Solder
R (max)	8.7 mOhm
Insert configuration value	0.305 - 5 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Contact Type	Solder
Max. Solid Conductor	0.09 mm <sup>2</sup> (AWG 28)
Max. Stranded Conductor	0.05 mm <sup>2</sup> (AWG 30)
Bucket Dia.	0.4 mm (0.016in)
Contact Dia.	0.35 mm (0.01in)
Low Voltage	5
Wire Size/AWG	36 - 28

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/egg-00-305-kll.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/egg-00-305-kll.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



Form & Material

Shell style / Model id	EG - Fixed receptacle, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (black chrome) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Weight	2.61 g

Environment

Environmental protection (IP rating)	IP50
Salt Spray Corrosion	>1000 hr

Drawings

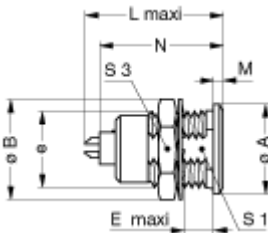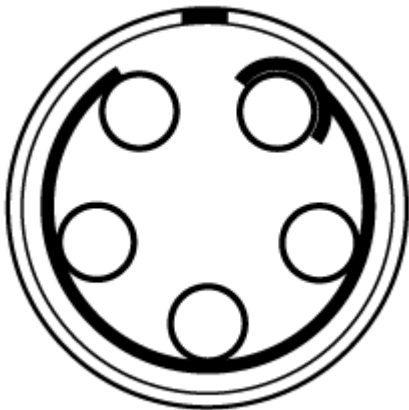

Dimensions

	B	e	L	M	N	S1	S3	A	E
mm.	10.3	M7x0.5	15.5	1	13.7	6.3	9	8	6
in.	0.41		0.61	0.04	0.54	0.25	0.35	0.31	0.24

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/egg-00-305-kl.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/egg-00-305-kl.html)

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.