



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

| | |
|------------------------------------|---|
| Number of contacts Low Voltage | 2 |
| Wire Size/AWG | 28 - 20 |
| Gender | Standard |
| Socket / Receptacle | Socket / Receptacle - Fixed Panel Front Mounted |
| Locking system | Push-pull |
| Jacket cable outside diameter [mm] | 1.00 - 8.30 mm |
| Size | 0T |
| Series | T - Small Outdoor keyed |

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/egg-0t-302-blln.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

| | |
|---------------------------------|-------------------------------|
| Number of contacts Low Voltage | 2 |
| Contact Termination Low voltage | Solder |
| R (max) | 4.8 mOhm |
| Insert configuration value | T.302 - 2 Low Voltage |
| Insulator | L: PEEK (UL 94 / V-0/1.5) |
| Rated current | 10 A |
| Vtest (contact-contact) | 1.9 kV (DC) |
| Vtest (contact-shell) | 1.5 kV (DC) |
| Max. Solid Conductor | 0.56 mm ² (AWG 20) |
| Max. Stranded Conductor | 0.56 mm ² (AWG 20) |
| Bucket Dia. | 1.0 mm (0.039in) |
| Contact Dia. | 0.9 mm (0.035in) |
| Wire Size/AWG | 28 - 20 |
| Gender | Standard |

Form & Material

| | |
|------------------------|--|
| Shell style / Model id | EG - Fixed receptacle, nut fixing, black POM outer shell |
| Socket / Receptacle | Fixed Panel Front Mounted |
| Housing material | POM (Polyoxymethylene, black) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces |
| Locking system | Push-pull |
| Keying | G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts) |
| Weight | 4.48 g |

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/egg-0t-302-blIn.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Environment

| | |
|-----------------------------------|---|
| Technical domain | Energy and Industrial, Test and Measurement |
| Environmental sealing (IP rating) | IP68 |
| Endurance | >3000 mating cycles |
| Climatical Category | 50/175/21 |
| Humidity (max) | <=95% [at 60 deg C /140 F] |
| Resistance to vibration | 15 g [10 Hz - 2000 Hz] |
| Shock Resistance | 100 g [6 ms] |

Cable fixation

| | |
|------------------------------------|----------------|
| Jacket cable outside diameter [mm] | 1.00 - 8.30 mm |
|------------------------------------|----------------|

Drawings

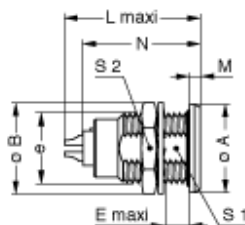

Dimensions

| | A | B | e | E | L | M | N | S1 | S2 |
|-----|------|------|--------|------|------|------|------|------|------|
| mm. | 12 | 12.5 | M9x0.6 | 6 | 21 | 1.5 | 19.1 | 8.2 | 11 |
| in. | 0.47 | 0.49 | | 0.24 | 0.83 | 0.06 | 0.75 | 0.32 | 0.43 |

Recommended By Lemo

Accessories

| | |
|----------------|--------------------------------|
| Compatible cap | BRE.0T.200.CAZ |
|----------------|--------------------------------|




















Tools

| | |
|---------|--------------------------------|
| Spanner | DCA.91.161.1TN |
|---------|--------------------------------|

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/egg-0t-302-blIn.html







LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cables

| Cable PartNumber | Material | Colour | Cable image |
|--------------------|----------|--------|---|
| CMN.02.T28.030PGCE | PVC | GREY |  |
| CMN.02.T28.030PGZE | | grey |  |
| CMN.02.T28.030PNCE | PVC | Black |  |
| CMN.02.T28.030PNZE | | |  |
| 102080 | PVC | Grey | |
| 120184 | PVC | Black |  |
| 120240 | PVC | Black |  |
| 120250 | PVC | Grey |  |
| 20140 | PVC | Grey |  |
| 20140 | PVC | Grey |  |
| 20141 | PVC | Grey |  |
| 20142 | PVC | Red |  |
| 20143 | PVC | Green |  |
| 20144 | PVC | Black |  |
| 20145 | PVC | Yellow |  |
| 20146 | PVC | Black |  |
| 20240 | PTFE | White |  |
| 20260 | PVC | Black |  |
| 20264 | PVC | Black |  |
| 20266 | PVC | Violet |  |

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/egg-0t-302-blIn.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

| Cable PartNumber | Material | Colour | Cable image |
|------------------|----------|--------|---|
| 2050 | PVC | Black |  |
| 20550 | PUR | Black |  |
| 20560 | PUR | White |  |
| 2080 | PVC | Grey | |
| 2221 | PVC | Black |  |
| 2260 | PTFE | White |  |
| 2280 | PVC | Black |  |
| 4082 | PVC | Grey | |
| CMB.02.210.635 | PUR | Black | |

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/egg-0t-302-blIn.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.