



Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	1
Wire Size/AWG	28 - 20
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.20 - 2.60 mm
Matching parts	ERA.00.113.CTL
Series	S - Indoor Stepped Insert

Technical details

Electrical Configuration

Contact Termination Low voltage	Solder
Insert configuration value	0.113 - 1 Low Voltage
Insulator	T: PTFE
Rated current	8 Amps
Vtest	850 V (AC), 1200 V (DC)
Contact Type	Solder
Contact Dia.	1.3
Number of contacts Low Voltage	1
Wire Size/AWG	28 - 20

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-00-113-ctal27.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Form & Material

Shell style / Model id	FFA - Straight plug with cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, male
Weight	3.01 g


Environment

Environmental protection (IP rating)	IP50
Salt Spray Corrosion	>1000 hr

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	2.20 - 2.60 mm

Drawings

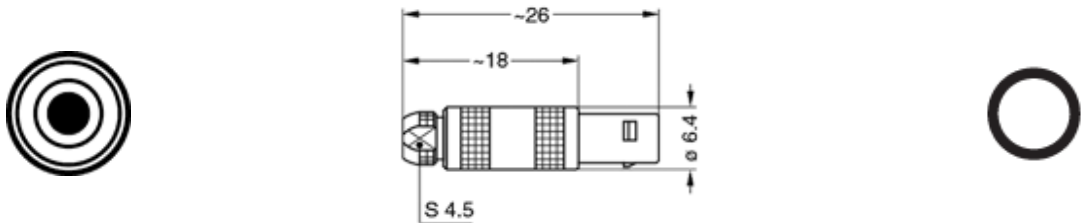

Dimensions

	A	L	M
mm.	6.4	26	18
in.	0.25	1.02	0.71