



Summary

[Request a quote](#)

[Catalog](#)

Low Voltage	13
Wire Size/AWG	28 - 20
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	7.10 - 8.00 mm
Size	4S
Matching parts	ERA.4S.313.CLL
Series	S - Indoor Stepped Insert

Technical details

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-4s-313-clac82z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Electrical Configuration

Contact Termination Low voltage	Solder
R (max)	3.6 mOhm
Insert configuration value	4S.313 - 13 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	9 Amps
Contact Type	Solder
Max. Solid Conductor	0.5 mm ² (AWG 20)
Max. Stranded Conductor	0.5 mm ² (AWG 20)
Bucket Dia.	1 mm (0.039in)
Contact Dia.	1.3 mm (0.051in)
Low Voltage	13
Wire Size/AWG	28 - 20

Form & Material

Shell style / Model id	FFA - Straight plug, cable collet and nut for fitting a bend relief
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with male pin 1
Variant	Nut for fitting a bend relief
Weight	151.88 g

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-4s-313-clac82z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental protection (IP rating)	IP50
Minimal temperature	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet
Jacket cable outside diameter [mm]	7.10 - 8.00 mm

Drawings

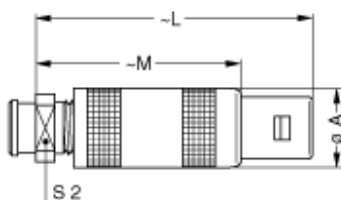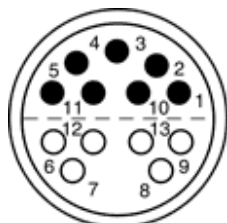

Dimensions

	L	M	S2	A
mm.	77	59	20	24.8
in.	3.03	2.32	0.79	0.98

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-4s-313-clac82z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Accessories

Compatible cap [BFA.4S.100.NAS](#)

Tools

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.13.T22.072QGZE	TPR (medical)	Grey	

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-4s-313-clac82z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.