



## Summary

[Request a quote](#)

[Catalog](#)

Coax	4
Number of contacts Low Voltage	9
Gender	Standard
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	12.10 - 12.80 mm
Size	4K
Matching parts	<a href="#">EGG.4K.879.CLL1</a>
Series	K - Outdoor keyed

## Technical details

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-4k-879-clac121.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-4k-879-clac121.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Electrical Configuration

Contact Termination Low voltage	Solder
Coax	4
Contact Termination Coax	Crimp
R (max)	5.8 mOhm
Insert configuration value	4K.879 - 4 Coax (50 Ohm), 9 Low V.
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	7 Amps
Test voltage (kV rms)	0.9
Contact Type	Coaxial 50 Ohm (Crimp) Type C
Cable type	Cable type: A RG 174 A/U, RG 188 A/U, RG 316 /U S
Contact Dia.	0.7 mm (0.03in)
Number of contacts Low Voltage	9
Gender	Standard

## Form & Material

Shell style / Model id	FG - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Weight	139.39 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental protection (IP rating)	IP68
Minimal temperature	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr


[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-4k-879-clac121.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-4k-879-clac121.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	12.10 - 12.80 mm

## Drawings

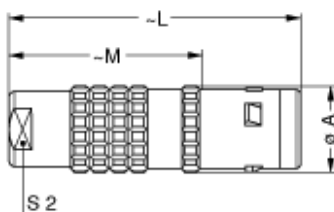

## Dimensions

	<b>S2</b>	<b>M</b>	<b>L</b>	<b>A</b>
mm.	19	50.5	71	25
in.	0.75	1.99	2.8	0.98

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-4k-879-clac121.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-4k-879-clac121.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.