



Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	4
Wire Size/AWG	34 - 28
Plug	Plug - Elbow
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.80 - 3.50 mm
Matching parts	EGG.00.304.CLL
Series	B - Indoor keyed

Technical details

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fpg-00-304-clad35z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Electrical Configuration

Contact Termination Low voltage	Solder
R (max)	8.7 mOhm
Insert configuration value	0.304 - 4 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	2 Amps
Vtest (contact-contact)	800 V (AC), 1130 V (DC)
Vtest (contact-shell)	650 V (AC), 920 V (DC)
Contact Type	Solder
Max. Solid Conductor	0.09 mm ² (AWG 28)
Max. Stranded Conductor	0.05 mm ² (AWG 30)
Bucket Dia.	0.4 mm (0.016in)
Contact Dia.	0.5 mm (0.02in)
Number of contacts Low Voltage	4
Wire Size/AWG	34 - 28

Form & Material

Shell style / Model id	FP - Elbow (90°) plug with cable collet for bend relief
Plug	Elbow
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Variant	Nut for fitting a bend relief
Weight	6.63 g

Environment

Environmental protection (IP rating)	IP50
Minimal temperature	-55°C / +250°C
Salt Spray Corrosion	>1000 hr


https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fpg-00-304-clad35z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet
Jacket cable outside diameter [mm]	2.80 - 3.50 mm

Drawings

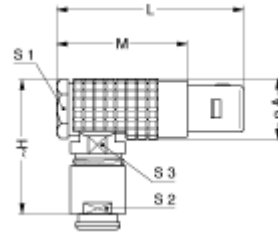

Dimensions

	A	H	L	M	S1	S2	S3
mm.	7.5	17.5	24.5	16.5	6.5	5	5.3
in.	0.3	0.69	0.96	0.65	0.26	0.2	0.21

Recommended By Lemo







Accessories

Tools

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fpg-00-304-clad35z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.04.T28.031PGCE	PVC	GREY	
CMN.04.T28.031PGZE		grey	
CMN.04.T28.031PNCE	PVC	Black	
CMN.04.T28.031PNZE			
CMN.04.T28.031QGC	TPR	Grey	
4041	PVC	Grey	
4050	PVC	Black	

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fpg-00-304-clad35z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.