



## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	5
Wire Size/AWG	24 - 24
Gender	Standard
Plug	Plug - Straight
Locking system	Threaded
Jacket cable outside diameter [mm]	4.60 - 5.00 mm
Size	0W
Matching parts	<a href="#">HRG.0W.305.CLLPV</a>
Series	W - Underwater

## Technical details

[https://www.lemo.com/int\\_en/solutions/supreme/w-underwater/fvg-0w-305-clac50z.html](https://www.lemo.com/int_en/solutions/supreme/w-underwater/fvg-0w-305-clac50z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Electrical Configuration

Contact Termination Low voltage	Solder
R (max)	6.1 mOhm
Insert configuration value	0W.305 - 5 Low Voltage
Rated current	6.5 Amps
Vtest (contact-contact)	1000 V (AC) 1400 V (DC)
Vtest (contact-shell)	700 V (AC) 1000 V (DC)
Contact Type	Solder
Max. Conductor	0.34 mm <sup>2</sup> (AWG 22)
Max. Stranded Conductor	0.34 mm <sup>2</sup> (AWG 22)
Bucket Dia.	0.8 mm (0.031in)
Contact Dia.	0.7 mm (0.028in)
Number of contacts Low Voltage	5
Wire Size/AWG	24 - 24
Gender	Standard

## Form & Material

Shell style / Model id	FV_/Z - Straight plug, cable collet and nut for fitting a bend relief
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Threaded
Keying	1 key (alpha=0, Plug: male contacts, Receptacle: female contacts)
Variant	Nut for fitting a bend relief
Weight	20.66 g

[https://www.lemo.com/int\\_en/solutions/supreme/w-underwater/fvg-0w-305-clac50z.html](https://www.lemo.com/int_en/solutions/supreme/w-underwater/fvg-0w-305-clac50z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



## Environment

Technical domain	Specialties and Other
Environmental protection (IP rating)	IP68
Minimal temperature	-20°C / +200°C
Climatical Category	20/200/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Pressure	30 bars
Salt Spray Corrosion	>1000 hr

## Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet
Jacket cable outside diameter [mm]	4.60 - 5.00 mm

## Drawings

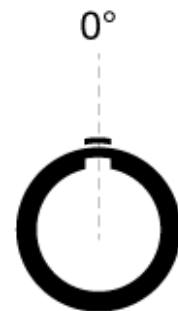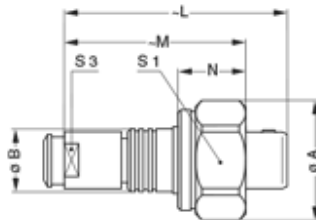

## Dimensions

	A	B	L	M	N	S1	S3
mm.	17.2	8.9	35.5	30.8	13.5	16	7
in.	0.68	0.35	1.4	1.21	0.53	0.63	0.28

[https://www.lemo.com/int\\_en/solutions/supreme/w-underwater/fvg-0w-305-clac50z.html](https://www.lemo.com/int_en/solutions/supreme/w-underwater/fvg-0w-305-clac50z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Recommended By Lemo

Accessories

---

Tools

---

## Cables

Cable PartNumber	Material	Colour	Cable image
50140	PVC	Grey	

---

[https://www.lemo.com/int\\_en/solutions/supreme/w-underwater/fvg-0w-305-clac50z.html](https://www.lemo.com/int_en/solutions/supreme/w-underwater/fvg-0w-305-clac50z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.