



Summary

[Request a quote](#)

[Catalog](#)

| | |
|------------------------------------|---|
| Number of contacts Low Voltage | 7 |
| Wire Size/AWG | 34 - 28 |
| Gender | Standard |
| Socket / Receptacle | Socket / Receptacle - Fixed Panel Front Mounted |
| Locking system | Push-pull |
| Jacket cable outside diameter [mm] | 1.00 - 12.60 mm |
| Size | 0K |
| Series | K - Outdoor keyed |

Technical details

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/hgg-0k-307-kllp.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Electrical Configuration

| | |
|---------------------------------|-------------------------------|
| Contact Termination Low voltage | Solder |
| R (max) | 8.7 mOhm |
| Insert configuration value | 0K.307 - 7 Low Voltage |
| Insulator | L: PEEK (UL 94 / V-0/1.5) |
| Rated current | 2.5 Amps |
| Vtest (contact-contact) | 800 V (AC), 1130 V (DC) |
| Vtest (contact-shell) | 700 V (AC), 990 V (DC) |
| Contact Type | Solder |
| Max. Solid Conductor | 0.09 mm ² (AWG 28) |
| Max. Stranded Conductor | 0.09 mm ² (AWG 28) |
| Bucket Dia. | 0.45 mm (0.018in) |
| Contact Dia. | 0.5 mm (0.02in) |
| Number of contacts Low Voltage | 7 |
| Wire Size/AWG | 34 - 28 |
| Gender | Standard |

Form & Material

| | |
|------------------------|---|
| Shell style / Model id | HG - Fixed receptacle, nut fixing, watertight or vacuum-tight |
| Socket / Receptacle | Fixed Panel Front Mounted |
| Housing material | Brass (black chrome) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces |
| Locking system | Push-pull |
| Keying | 1 key (alpha=0, plug: male contacts, receptacle: female contacts) |
| Variant | Watertight unmated (connector to device) |
| Weight | 12.61 g |

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/hgg-0k-307-klp.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



Environment

| | |
|--------------------------------------|---|
| Technical domain | Audio Video, Energy and Industrial, Medical, Test and Measurement |
| Environmental protection (IP rating) | IP68 |
| Minimal temperature | -20°C / +100°C |
| Climatical Category | 20/80/21 |
| Humidity (max) | <=95% [at 60 deg C /140 F] |
| Shielding (min) | 95 dB (10 MHz) |
| Shielding (min) | 80 dB (1 GHz) |
| Shock Resistance | 100 g [6 ms] |
| Vibration | 15 g [10 Hz - 2000 Hz] |
| Pressure | 60 bars |
| Salt Spray Corrosion | >1000 hr |

Cable fixation

| | |
|------------------------------------|-----------------|
| Jacket cable outside diameter [mm] | 1.00 - 12.60 mm |
|------------------------------------|-----------------|

Drawings

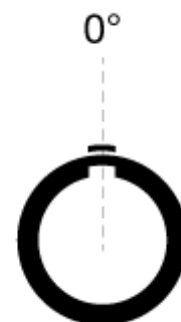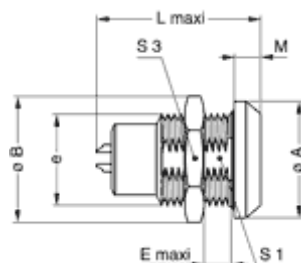

Dimensions

| | S3 | A | B | e | E | L | M | S1 |
|-----|-----------|----------|----------|----------|----------|----------|----------|-----------|
| mm. | 17 | 18 | 19.5 | M14x1.0 | 5.5 | 21.7 | 4 | 12.5 |
| in. | 0.67 | 0.71 | 0.77 | | 0.22 | 0.85 | 0.16 | 0.49 |

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/hgg-0k-307-klp.html







LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Accessories

Tools

Cables

| Cable PartNumber | Material | Colour | Cable image |
|--------------------|----------|--------|---|
| CMN.07.T28.044PGZE | | grey |  |
| CMN.07.T28.044PNZE | | |  |
| 7041 | PVC | Grey |  |
| 7050 | PVC | Black |  |
| 717920 | PVC | Grey |  |
| CTR.75.030.121875G | PVC | Grey |  |

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/hgg-0k-307-klp.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.