



Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	3
Wire Size/AWG	16 - 12
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Free
Locking system	Push-pull
Jacket cable outside diameter [mm]	7.60 - 8.00 mm
Size	3K
Matching parts	FGG.3K.303.CYCC80Z
Series	K - Outdoor keyed

Technical details

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/phg-3k-303-cymc80z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Electrical Configuration

Contact Termination Low voltage	Crimp
R (max)	3.3 mOhm
Insert configuration value	3K.303 - 3 Low Voltage
Insulator	Y: PEEK for crimp contacts
Rated current	25 Amps
Vtest (contact-contact)	3200 V (AC), 4530 V (DC)
Vtest (contact-shell)	2650 V (AC), 3750 V (DC)
Contact retention	65 N
Contact Type	Crimp
Max. Conductor	2.5 mm ² (AWG 12)
Min. Conductor	1.5 mm ² (AWG 16)
Bucket Dia.	2.4 mm (0.094in)
Contact Dia.	2 mm (0.079in)
Number of contacts Low Voltage	3
Wire Size/AWG	16 - 12
Gender	Standard

Form & Material

Shell style / Model id	PH - Free receptacle, cable collet and nut for fitting a bend relief
Socket / Receptacle	Free
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Variant	Nut for fitting a bend relief

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/phg-3k-303-cymc80z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental protection (IP rating)	IP68
Minimal temperature	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet
Jacket cable outside diameter [mm]	7.60 - 8.00 mm

Drawings

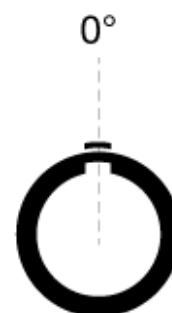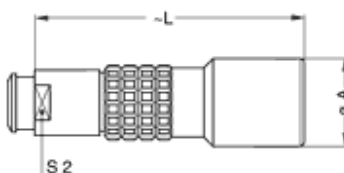

Dimensions

	A	L	S2
mm.	23	64	15
in.	0.91	2.52	0.59

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/phg-3k-303-cymc80z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Accessories	
Replacement contact	EGG.3B.675.ZZM
Tools	
Positionner	DCE.91.203.BVCM
Extraction tool	DCC.20.25B.LAG
Crimp tool	DPC.91.101.A
Spanner wrench	DCD.3E.ZZZ.PA150

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.03.T14.078PGCE			
330150	PVC	Grey	