



Summary

[Request a quote](#)

[Catalog](#)

| | |
|------------------------------------|---|
| Low Voltage | 30 |
| Wire Size/AWG | 26 - 22 |
| Gender | Reverse Gender |
| Socket / Receptacle | Socket / Receptacle - Fixed Panel Front Mounted |
| Locking system | Push-pull |
| Jacket cable outside diameter [mm] | 9.30 - 10.00 mm |
| Size | 3B |
| Series | B - Indoor keyed |

Technical details

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/pkk-3b-330-cycd10z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Electrical Configuration

| | |
|---------------------------------|-------------------------------|
| Contact Termination Low voltage | Crimp |
| R (max) | 6.1 mOhm |
| Insert configuration value | 3B.330 - 30 Low Voltage |
| Insulator | Y: PEEK for crimp contacts |
| Rated current | 3.5 Amps |
| Vtest (contact-contact) | 1350 V (AC), 1910 V (DC) |
| Vtest (contact-shell) | 1200 V (AC), 1700 V (DC) |
| Contact retention | 22 N |
| Contact Type | Crimp |
| Max. Conductor | 0.34 mm ² (AWG 22) |
| Min. Conductor | 0.14 mm ² (AWG 26) |
| Bucket Dia. | 0.8 mm (0.031in) |
| Contact Dia. | 0.7 mm (0.028in) |
| Low Voltage | 30 |
| Wire Size/AWG | 26 - 22 |
| Gender | Reverse Gender |

Form & Material

| | |
|------------------------|---|
| Shell style / Model id | PK - Fixed receptacle, nut fixing, cable collet and nut for fitting a bend relief |
| Socket / Receptacle | Fixed Panel Front Mounted |
| Housing material | Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces |
| Locking system | Push-pull |
| Keying | 2 keys (alpha=52.5, plug: female contacts, receptacle: male contacts) |
| Variant | Nut for fitting a bend relief |
| Weight | 55.01 g |

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/pkk-3b-330-cycd10z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



Environment

| | |
|--------------------------------------|--|
| Technical domain | Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV |
| Environmental protection (IP rating) | IP50 |
| Minimal temperature | -55°C / +250°C |
| Climatical Category | 50/175/21 |
| Humidity (max) | <=95% [at 60 deg C /140 F] |
| Shielding (min) | 75 dB (10 MHz) |
| Shielding (min) | 40 dB (1 GHz) |
| Shock Resistance | 100 g [6 ms] |
| Vibration | 15 g [10 Hz - 2000 Hz] |
| Salt Spray Corrosion | >1000 hr |

Cable fixation

| | |
|------------------------------------|-----------------------|
| Cable termination protection | For cable bend relief |
| Fixation type | Cable collet |
| Jacket cable outside diameter [mm] | 9.30 - 10.00 mm |

Drawings

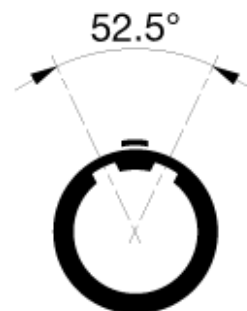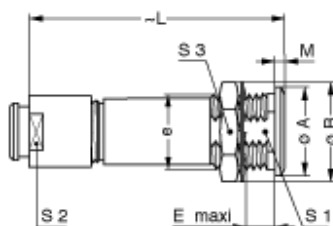

Dimensions

| | A | B | e | E | L | S3 | S1 | S2 | M |
|-----|------|------|---------|------|------|------|------|------|------|
| mm. | 22 | 25 | M18x1.0 | 11.5 | 54.5 | 22 | 16.5 | 14 | 2 |
| in. | 0.87 | 0.98 | | 0.45 | 2.15 | 0.87 | 0.65 | 0.55 | 0.08 |

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/pkk-3b-330-cycd10z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.